

# Punchdown Consolidation Point Enclosure

## specifications

Punchdown consolidation point enclosure shall be made of 16 gauge aluminum and shall be available empty. Enclosure shall be wall mounted horizontally or vertically and shall be Plenum rated. Enclosure shall accept Category 5e, Category 6 or Category 6A cabling, and include a removable cover, which shall provide top and bottom access to cables.



## technical information

<b>Consolidation point:</b>	Follows TIA/EIA 568-B standard
<b>Plenum rated:</b>	UL 2043
<b>Dimensions:</b>	3.44"H x 9.47"W x 13.22"L (87.4mm x 240.5mm x 335.8mm)
<b>Mounting options:</b>	Can be easily wall mounted horizontally or vertically
<b>Materials:</b>	Made of 16 gauge aluminum

## key features and benefits

<b>Unpopulated enclosure</b>	Allows a choice of Panduit punchdown bases to be used for added versatility
<b>Cable access</b>	Top and bottom cable entry offers flexibility in any application
<b>Keyless lock</b>	Slot lock to keep enclosure closed
<b>Simplified moves, adds and changes</b>	Reduces down time and labor cost associated with MACs
<b>Cable capacity</b>	Knockout cable openings are designed for use with Category 6A cabling

## applications

The punchdown consolidation point enclosure mounts to the wall above and below the ceiling to consolidate several outlets in one location.

This solution provides flexibility in changing network environments as increasing capacity is demanded. This enclosure is designed to provide an efficient and cost effective way

to deploy cabling systems for open office architecture. Consolidation point boxes save time and labor costs by reducing the amount of time and cable required to complete moves, adds and changes. They serve as a transition point between the horizontal cable coming out of the main closet and the cable going into the workstation.

### Punchdown Consolidation Point Enclosure

**Empty enclosure:** WMCPE

### Punchdown Bases

**24 pair, Category 6:** GPB24-X  
**144 pair, Category 6:** GPB144-X  
**100 pair, 110:** P110B100-X

### Giga-Punch™ Accessories

**4 pair connecting block:** GPCB4-XY

**5 pair connecting block:** GPCB5-XY

### Pan-Punch® Accessories

**3 pair connecting block:** P110CB3-XY

**4 pair connecting block\*\*:** P110CB4-XY

**5 pair connecting block\*\*:** P110CB5-XY

### Punchdown Termination Tools

**Giga-Punch™ 4 Pair Punchdown Tool:** GPDTM

**Pan-Punch® Single Pair Punchdown Tool:** PDT110




**Pan-Punch® 5 Pair Punchdown Tool:** PDT110M

### Punchdown Label Holder

**Label holder for 110 and GP6™ Bases:** P110LH

\*\*International Gray Connecting Blocks available

# Punchdown Consolidation Point Enclosure

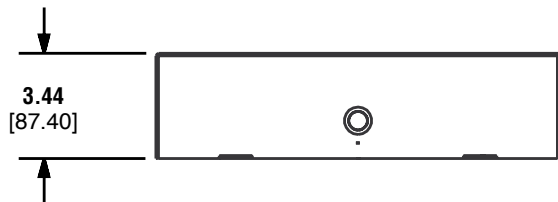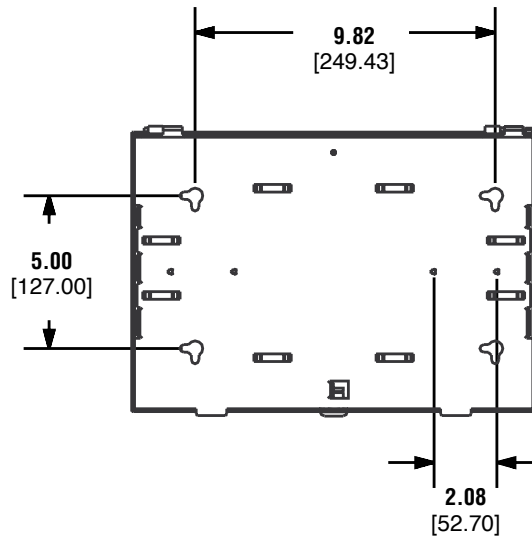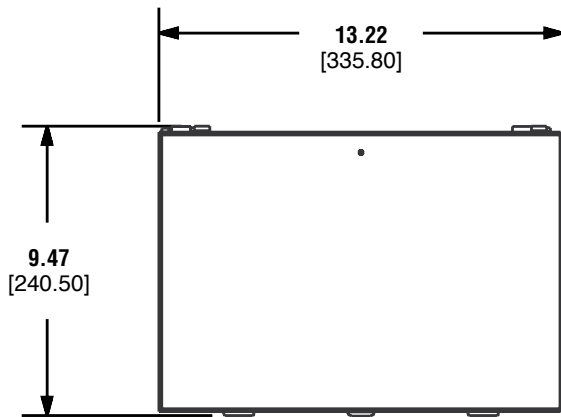

Dimensions are in inches. [Dimensions in brackets are metric].

## WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT CANADA  
Markham, Ontario  
cs-cdn@panduit.com  
Phone: 800.777.3300

PANDUIT EUROPE LTD.  
London, UK  
cs-emea@panduit.com  
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.  
Republic of Singapore  
cs-ap@panduit.com  
Phone: 65.6305.7575

PANDUIT JAPAN  
Tokyo, Japan  
cs-japan@panduit.com  
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA  
Jalisco, Mexico  
cs-la@panduit.com  
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.  
Victoria, Australia  
cs-aus@panduit.com  
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to [www.panduit.com/warranty](http://www.panduit.com/warranty)

For more information

Visit us at [www.panduit.com](http://www.panduit.com)

Contact Customer Service by email: [cs@panduit.com](mailto:cs@panduit.com)  
or by phone: 800-777-3300

**PANDUIT**<sup>®</sup>

©2016 Panduit Corp.  
ALL RIGHTS RESERVED.  
**RKSP160--WW-ENG**  
Replaces WW-RKSP49  
2/2016